



order on
VWR.COM

WELLS LAMONT
Industrial

hand protection solutions



about us

Wells Lamont Industrial provides a comprehensive selection of gloves which can help protect your hands from cuts, impact, abrasions, heat, and cold. We are ready to help you handle the toughest applications in general industry, pharmaceutical areas, cleanrooms, research laboratories, and industrial environments.

Our products are made with the finest materials and advanced technology, so you can be assured the gloves you're wearing provide maximum value and can help you perform at your best.

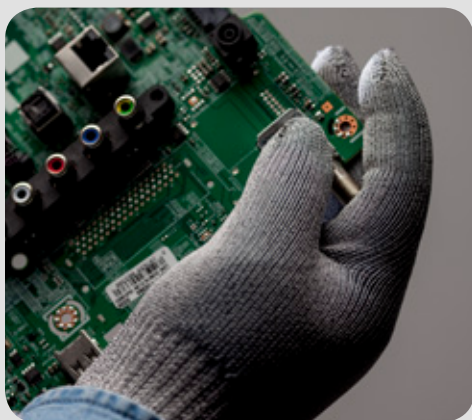


table of contents

nylon liners.....	3
sterile liners	4
cut resistant.....	4
cut resistant liners.....	5
cut resistant coated palm.....	6
fully coated.....	7
general purpose coated palm.....	7
heat.....	8
sleeves	8
thermal.....	9
leather	10
impact.....	11
mechpro.....	11

Highly Reusable Nylon Liner

- 100% continuous nylon makes this liner thin and comfortable
- Fully launderable up to 30 times without shrinkage
- Category II - >.3um & >.5um

Full Finger – Dozen Pair

WLI Part No.	VWR Cat. No.
M005S.WLC	32935-559
M005M.WLC	32935-561
M005L.WLC	32935-563
M005XL.WLC	32935-565



Full Finger – 20 Pairs Polybag

WLI Part No.	VWR Cat. No.
M555S	32935-581
M555M	32935-583
M555L	32935-585
M555XL	32935-587



Half Finger

WLI Part No.	VWR Cat. No.
M006M.WLC (Men's)	32935-569
M006W.WLC (Women's)	32935-567

Reusable Nylon Liner

- Stretch nylon construction improves comfort and flexibility
- Form fitting design is perfect for high dexterity applications
- Sold by the dozen pair

Full Finger

WLI Part No.	VWR Cat. No.
M089	32935-536



Half Finger

WLI Part No.	VWR Cat. No.
M088	32935-480



Medical Nylon Liner

- 100% continuous nylon creates an ideal barrier between hands and latex gloves
- Fully launderable up to 20 times without shrinking
- Available in full or half finger
- Sold by the box (25 pieces per box)

Full Finger

WLI Part No.	VWR Cat. No.
M115S	14224-270
M115M	13500-888
M115L	14224-272



Half Finger

WLI Part No.	VWR Cat. No.
M117M (Men's)	14224-274
M117W (Women's)	14224-276



Medical Nylon Liner, Extended Cuff

- 100% continuous nylon creates an ideal barrier between hands and latex gloves
- Fully launderable up to 20 times without shrinking
- Sold by the box (25 pieces per box)

WLI Part No. VWR Cat. No.

M113S	32935-100
M113M	32935-102
M113L	32935-104



Disposable Cotton Liner

- Lightweight 100% cotton liner for single use
- Absorbs moisture and provides tactile sensitivity
- Sold by the dozen pair

WLI Part No. VWR Cat. No.

Y6701L (Men's)	32935-460
Y6701W (Women's)	32935-461



sterile liners

Spec-Tec™ Sterile

- 100% Spectra® fiber construction
- Excellent tactile sensitivity
- ANSI Cut Level A1
- Each pair in sterile packaging
- Sold by the box (20 pieces per box)

WLI Part No.	VWR Cat. No.
M102S	80091-126
M102M	80091-124
M102L	80091-122



Scepter™ Sterile

- Stainless steel and polyester construction
- Moderate tactile sensitivity
- Antimicrobial
- ANSI Cut Level A4
- Each pair in sterile packaging
- Sold by the box (20 pieces per box)

WLI Part No.	VWR Cat. No.
M321S	52428-890
M321M	52428-892
M321L	52428-894
M321XL	52428-896



cut resistant

Silver Talon

- Unmatched combination of cut resistance, dexterity and durability
- Unique colored cuff is highly visible
- CFR 21 – approved for food contact
- Ambidextrous
- ANSI Cut Level A6
- Sold by 6 pieces

Size	WLI Part No.	VWR Cat. No.
XXS	132524	14231-961
XS	134525	32935-159
S	134526	32935-161
M	134527	32935-163
L	134528	32935-165
XL	132529	32935-167



Stainless Steel Mesh Hand Glove

- Micro plasma welded rings have no gaps to trap soil that can feed bacterial growth
- Self-adjusting tensioning system on wrist allows for an easy fit
- Ambidexterous
- Sold by the piece

Size	WLI Part No.	VWR Cat. No.
XS	CM030001	80091-048
S	CM030002	80091-050
M	CM030003	80091-052
L	CM030004	80091-054
XL	CM030005	80091-056
XXL	CM030006	80091-058



cut resistant liners

Cut Resistant Liner

- High performance fiber with stretch
- Moderate tactile sensitivity
- ANSI Cut Level A2
- Sold by the dozen pair

WLI Part No.	VWR Cat. No.
M214XS	32935-509
M214S	32935-481
M214M	32935-483
M214L	32935-485
M214XL	32935-487



Touchscreen Cut Resistant Liner

- Lightweight construction delivers superior tactile sensitivity
- Touchscreen compatible
- Category III - $>.3\mu\text{m}$
- Category II - $>.5\mu\text{m}$
- ANSI Cut Level A4
- Sold by the dozen pair

WLI Part No.	VWR Cat. No.
MT130XS	10153-784
MT130S	10153-786
MT130M	10153-788
MT130L	10153-790
MT130XL	10153-780



Scepter™

- Thin gauge stainless steel wrapped in polyester
- Moderate tactile sensitivity
- ANSI Cut Level A4
- Ambidexterous
- Sold by the box (10 pieces per box)

WLI Part No.	VWR Cat. No.
M121XS	75836-512
M121S	75836-514
M121M	75836-516
M121L	75836-518
M121XL	75836-520



Cut Resistant Liner

- Stainless steel and polyester construction
- Moderate tactile sensitivity
- Black color hides dirt
- Category III - $>.3\mu\text{m}$ & $>.5\mu\text{m}$
- ANSI Cut Level A4
- Sold by the dozen pair

WLI Part No.	VWR Cat. No.
M281S	32935-392
M281M	32935-394
M281L	32935-396
M281XL	32935-398



Kevlar® Liner

- Light weight Kevlar® fibers offer minor cut resistance without compromising tactile sensitivity
- ANSI Level A2
- Ambidexterous
- Sold by the dozen pair

WLI Part No.	VWR Cat. No.
M79S	80091-677
M79M	32935-155
M79L	32935-157



ANSI/ISEA 105-2016	
Level	Gram Range
-	<200
A1	≥ 200
A2	≥ 500
A3	$\geq 1,000$
A4	$\geq 1,500$
A5	$\geq 2,200$
A6	$\geq 3,000$
A7	$\geq 4,000$
A8	$\geq 5,000$
A9	$\geq 6,000$

ANSI Cut Rating Levels

When tested in accordance with ASTM F2992-15 Test Methods for Measuring Cut Resistance of Materials used in Protective Clothing, the glove's resistance is classified against levels, using the weight needed to cut through the material with 20mm (0.78") of blade travel.

cut resistant coated palm

FlexTech™ Y9216 Cut Shell Nitrile Palm

- Cut resistant shell provides all-day comfort and protection
- Sandy nitrile palm coating delivers improved grip
- ANSI Cut Level A7
- Sold by the dozen pair

Size	WLI Part No.	VWR Cat. No.
XS	Y9216XS	10847-276
S	Y9216S	10847-278
M	Y9216M	10847-296
L	Y9216L	10847-298
XL	Y9216XL	10847-300
XXL	Y9216XXL	10847-302



FlexTech™ Y9236 Cut Shell with Nitrile Palm

- High performance and cooling fibers ensures comfort in warm work environments
- Sandy nitrile palm provides excellent grip
- Hi-visibility color improves awareness
- Reinforced thumb crotch provides extended wear
- ANSI Cut Level A4
- Sold by the dozen pair

Size	WLI Part No.	VWR Cat. No.
XS	Y9236XS	75875-668
S	Y9236S	75875-670
M	Y9236M	75875-672
L	Y9236L	75875-674
XL	Y9236XL	75875-676
XXL	Y9236XXL	75875-678



Vis-Tech™ Y9294 with PU Palm

- Hi-vis cut resistant shell delivers outstanding comfort, flexibility, protection and visibility
- Polyurethane (PU) palm coating
- ANSI Cut Level A4
- Sold by the dozen pair

Size	WLI Part No.	VWR Cat. No.
XS	Y9294XS	10014-240
S	Y9294S	10014-174
M	Y9294	10014-176
L	Y9294L	10014-178
XL	Y9294XL	10014-180
XXL	Y9294XXL	10014-182



Vis-Tech™ Y9296 with Nitrile Palm

- Hi-vis cut resistant shell provides visibility
- Sandy nitrile excellent for grip and handling small parts
- ANSI Cut Level A4
- Sold by the dozen pair

Size	WLI Part No.	VWR Cat. No.
XS	Y9296XS	10014-184
S	Y9296S	10014-186
M	Y9296	10014-188
L	Y9296L	10014-190
XL	Y9296XL	10014-192
XXL	Y9296XXL	10014-194



FlexTech™ Y9265 HPPE Shell with PU Palm

- High performance polyethylene (HPPE) shell
- Polyurethane (PU) palm coating is thin and flexible
- Gray fibers hide dirt and grime
- ANSI Cut Level A2
- Sold by the dozen pair

Size	WLI Part No.	VWR Cat. No.
XS	Y9265XS	89030-788
S	Y9265S	89030-790
M	Y9265M	89030-792
L	Y9265L	89030-794
XL	Y9265XL	89030-796



FlexTech™ Y9266 HPPE Shell with PU Palm

- High performance polyethylene fibers (HPPE) shell
- PU palm coating provides excellent grip
- Provides the best balance of comfort and dexterity
- ANSI Cut Level A2
- Sold by the dozen pair

Size	WLI Part No.	VWR Cat. No.
XS	Y9266XS	89030-812
S	Y9266S	80092-414
M	Y9266M	80092-412
L	Y9266L	80092-410
XL	Y9266XL	80092-416



fully coated

FlexTech™ Y9290

- Cut resistant knit shell
- Sandy nitrile coated palm and fingertips for grip
- Full NBR coating provides layer of protection against liquids
- Liquid resistant
- ANSI Cut Level A4
- Sold by the dozen pair

Size	WLI Part No.	VWR Cat. No.
S	Y9290S	10859-872
M	Y9290M	10859-874
L	Y9290L	10859-876
XL	Y9290XL	10859-878
XXL	Y9290XXL	10859-880



FlexTech™ Y9289

- Light weight synthetic knit shell
- Sandy nitrile coated palm and fingertips for grip
- Full NBR coating provides layer of protection against liquids
- Offers great flexibility and dexterity
- ANSI Cut Level A1

Size	WLI Part No.	VWR Cat. No.
XS	Y9289XS	75836-500
S	Y9289S	75836-502
M	Y9289M	75836-540
L	Y9289L	75836-542
XL	Y9289XL	75836-544
XXL	Y9289XXL	75836-546



general purpose coated palm

FlexTech™ Y9297W

- Light weight synthetic knit shell
- PU palm coating provides grip
- Silicone Free
- ANSI Cut Level A1
- Sold by the dozen pair

Size	WLI Part No.	VWR Cat. No.
XS	Y9297W-6	76196-492
S	Y9297W-7	76196-494
M	Y9297W-8	76196-496
L	Y9297W-9	76196-498
XL	Y9297W-10	76196-500
XXL	Y9297W-11	76196-502



FlexTech™ Y9277

- Lightweight shell delivers comfort
- PU palm coating is thin and flexible
- Gray fibers hide dirt and grime
- ANSI Cut Level A1
- Sold by the dozen pair

Size	WLI Part No.	VWR Cat. No.
XS	Y9277XS	89030-798
S	Y9277S	89030-800
M	Y9277M	89030-802
L	Y9277L	89030-804
XL	Y9277XL	89030-806
XXL	Y9277XXL	75836-538



FlexTech™ Y9287

- Lightweight shell delivers comfort
- PU palm coating is thin and flexible
- Black fibers hide dirt and grime
- ANSI Cut Level A1
- Sold by the dozen pair

Size	WLI Part No.	VWR Cat. No.
XS	Y9287XS	89429-166
S	Y9287S	89429-168
M	Y9287M	89429-170
L	Y9287L	89429-172
XL	Y9287XL	89429-174



FlexTech™ Y9249

- Light weight, synthetic knit shell
- Foam nitrile palm provides excellent grip
- Ideal for dry and slightly oily applications
- ANSI Cut Level A1
- Sold by the dozen pair

Size	WLI Part No.	VWR Cat. No.
XS	Y9249XS	89040-184
S	Y9249S	89040-186
M	Y9249M	89040-188
L	Y9249L	89040-190
XL	Y9249XL	89040-192



heat

FR Heat Glove

- Protects up to 450°F
- FR cotton outer shell
- Cotton lined
- 5" gauntlet
- Loop-out
- Heat and flame retardant
- Sold by the dozen pair

Size	WLI Part No.	VWR Cat. No.
XL	636HRLFR	80091-480



Kevlar/Nomex® Seamless Glove

- Protects up to 500°F
- Kevlar/Nomex outer shell provides mobility, allowing wearer to handle hot objects
- Fully lined with cotton for softness
- Ambidexterous
- Continuous cuff
- Sold by dozen pieces

Size	WLI Part No.	VWR Cat. No.
S	2610S	75836-504
M	2610M	75836-506
L	2610L	75836-508
XL	2610XL	75836-510



KELKLAVE® Autoclave Gloves

- Protects up to 250°F
- White loop-out terry cloth
- Gauntlet cuff
- Clute cut
- Sold by the dozen pair

Cuff Size	WLI Part No.	VWR Cat. No.
5"	422-5	80091-460
11"	422-11	80091-458



sleeves

Medical Sleeve

- Protects from bites and scratches
- Soft, comfortable, and breathable nylon construction for all day wear
- Poly/cotton plaiting for added comfort
- Tapered for extra stretch at the bicep
- Elastic on both ends helps sleeve to stay in place
- Latex-free
- ANSI Cut Level A2
- Sold by dozen pieces

Length	WLI Part No.	VWR Cat. No.
18"	ADM-18	75818-192
24"	ADM-24	75818-194



100% Kevlar® Sleeve

- 2-ply knit sleeve
- Flame resistant
- Made from 100% Kevlar
- ANSI Cut Level A3
- Sold by dozen pieces

Length	WLI Part No.	VWR Cat. No.
10"	SK-10	14233-290
14"	SK-14	800091-776
16"	SK-16	800091-784
18"	SK-18	32935-690



Terry Sleeve

- Protects up to 350°F
- White cut & sewn sleeve, loop-out
- Elastic top secures sleeve to upper arm
- Sold by dozen pieces

Length	WLI Part No.	VWR Cat. No.
14"	S-15HR, knit wrist	80091-756
16"	S-14HR, knit wrist	80091-754
19"	S-11HR, hemmed bottom	80091-752



FlexTech™ Y9239T

- Synthetic shell delivers comfort and dexterity
- Sandy latex palm provides outstanding grip and flexibility
- Hi-visibility color improves hand awareness
- Brushed fleece liner keeps hands warm
- Used in cold storage labs
- ANSI Cut Level A3
- Sold by the dozen pair

WLI Part No.	VWR Cat. No.
Y9239TM	10066-724
Y9239TL	10066-726
Y9239TXL	10066-728
Y9239TXXL	10066-730



FlexTech™ I2449T

- Soft and flexible TPR pads protect from impacts and blows to the back of the hand and fingers
- Machine knit shell delivers excellent comfort and dexterity
- Sandy nitrile palm maintains a firm grip
- Hi-vis color improves compliance
- Brushed fleece liner keeps hands warm
- ANSI Cut Level A3
- Sold by the dozen pair

Size	WLI Part No.	VWR Cat. No.
S	I2449TS	10847-256
M	I2449TM	10847-258
L	I2449TL	10847-260
XL	I2449TXL	10847-262
XXL	I2449TXXL	10847-264



FlexTech™ Y9241T

- Hi-vis orange shell provides a high level of protection & creates awareness in tough environments
- 3/4 dip Sandy Nitrile palm coating provides excellent grip and tactility
- Thermal Acrylic Fleece Lining
- Knit wrist prevents dirt and debris from entering the glove
- ANSI Cut Level A2
- Sold by the dozen pair

Size	WLI Part No.	VWR Cat. No.
M	Y9241TM	76204-674
L	Y9241TL	76204-656
XL	Y9241TXL	76204-658
XXL	Y9241TXXL	76204-660



MechPro® Insulated

- Synthetic leather palm and finger
- Lining for colder environments
- Reinforced fingertips with improved pinched fingertip design
- Hook and loop wrist closure
- Sold by the dozen pair

Size	WLI Part No.	VWR Cat. No.
M	7750M	80091-506
L	7750L	80091-504
XL	7750XL	80091-508



leather

Grain Leather Driver

- Quality cowhide
- Gunn cut
- Straight thumb
- Bound hem
- Double shirred elastic wrist
- Sold by the dozen pair

Size	WLI Part No.	VWR Cat. No.
S	Y0122S	32935-448
M	Y0122M	32935-449
L	Y0122L	32935-450
XL	Y0122XL	32935-451
XXL	Y0122XXL	89030-818



Grain Leather Driver

- Standard cowhide
- Gunn cut
- Straight thumb
- Bound hem
- Shirred elastic wrist keeps dirt out
- Sold by the dozen pair

Size	WLI Part No.	VWR Cat. No.
S	Y0135S	80091-892
M	Y0135M	80091-890
L	Y0135L	80091-888
XL	Y0135XL	80091-894



Grips® Ball & Tape Driver

- Premium quality grain cowhide
- Ball and tape adjustable wrist closure keeps dirt and debris out
- Gunn cut
- Straight thumb
- Bound hem
- Sold by the dozen pair

Size	WLI Part No.	VWR Cat. No.
S	1178S	80091-322
M	1178M	80091-320
L	1178L	80091-318
XL	1178XL	80091-324
XXL	1178XXL	80091-326



Grain Pigskin Driver with Orange Mesh Back

- Quality grain pigskin palm for comfort
- Hi-vis orange mesh back for better air circulation and visibility
- Hi-vis yellow reflective knuckle straps for more protection and visibility
- Gunn cut
- Keystone thumb
- Double-shirred elastic wrist
- Sold by the dozen pair

Size	WLI Part No.	VWR Cat. No.
S	Y0325S	76204-674
M	Y0325M	76204-676
L	Y0325L	76204-678
XL	Y0325XL	76204-780
XXL	Y0325XXL	76204-782



Pig Driver

- Quality pigskin
- Keystone thumb for superior flexibility
- Double elastic shirred back
- Gunn cut
- Bound hem
- Sold by the dozen pair

Size	WLI Part No.	VWR Cat. No.
S	Y0323S	80091-920
M	Y0323M	80091-918
L	Y0323L	80091-916
XL	Y0323XL	80091-914



Leather Driver with Cut Resistant Liner

- Soft and flexible goatskin leather
- Kevlar® liner delivers cut protection
- Straight thumb
- Double shirred elastic wrist
- ANSI Cut Level A3
- Sold by the dozen pair

Size	WLI Part No.	VWR Cat. No.
S	Y0103S	10847-316
M	Y0103M	10847-318
L	Y0103L	10847-320
XL	Y0103XL	10847-322
XXL	Y0103XXL	10847-324



Kevlar® Lined Leather Impact Driver

- Goatskin offers comfort and durability
- Kevlar® liner delivers cut protection
- Soft and flexible TPR protects hand and fingers
- Gunn cut pattern
- ANSI Cut Level A3
- Sold by the dozen pair

Size	WLI Part No.	VWR Cat. No.
S	I2430S	76196-504
M	I2430M	76196-506
L	I2430L	76196-508
XL	I2430XL	76196-510
XXL	I2430XXL	76196-512



Hi-Vis Cut Level A4 Nitrile Palm with Impact

- Soft and flexible TPR pads protect against blows to the back of the hands and fingers
- Sandy nitrile palm provides excellent grip
- Reinforced thumb crotch provides an extra layer of protection between thumb and forefinger, while providing extended wear
- Hi-visibility color improves awareness
- ANSI Cut Level A4
- Sold by the dozen pair

Size	WLI Part No.	VWR Cat. No.
S	I2469S	75875-660
M	I2469M	75875-662
L	I2469L	75875-680
XL	I2469XL	75875-664
XXL	I2469XXL	75875-666



MechPro® Grip

- Premium pigskin leather
- Reinforced padded palm patch for grip and vibration resistance
- Reinforced leather thumb, fingertips and knuckle strap for extra wear
- Padded palm for extra protection
- Hook and loop adjustable wrist closure
- Sold by the dozen pair

Size	WLI Part No.	VWR Cat. No.
M	7790M	83008-012
L	7790L	83008-014
XL	7790XL	83008-016



MechPro® Plus

- Synthetic leather palm and finger
- Reinforced padded palm patch for grip and vibration resistance
- Improved pinched fingertip design and gusseted finger crotch for comfort
- Padded palm for extra protection
- Hook and loop adjustable wrist closure
- Sold by the dozen pair

Size	WLI Part No.	VWR Cat. No.
S	Y7711S	83007-994
M	Y7711M	83007-996
L	Y7711L	83007-998
XL	Y7711XL	83008-002



MechPro®

- Ribbed knit fabric for nick, abrasion and incidental protection
- Synthetic leather palm and fingertips
- Reinforced fingertips with improved pinched fingertip design
- Gusseted finger crotch and perforated finger fourchettes for comfort
- Hook and loop adjustable wrist closure
- Sold by the dozen pair


Size	WLI Part No.	VWR Cat. No.
S	7701S	83007-986
M	7701M	83007-988
L	7701L	83007-990
XL	7701XL	83007-992





WELLS LAMONT Industrial

 © 2019 Wells Lamont Industrial
PW 1878



1.800.932.5000 | VWR.COM

Prices and product details are current when published and subject to change without notice. | Certain products may be limited by federal, state, provincial, or local regulations. | VWR, part of Avantor, makes no claims or warranties concerning sustainable/green products. Any claims concerning sustainable/green products are the sole claims of the manufacturer and not those of VWR International, LLC and/or Avantor, Inc. or affiliates. All prices are in US dollars unless otherwise noted. Offers valid in US and Canada, void where prohibited by law or company policy, while supplies last. | Trademarks are owned by Avantor, Inc. or its affiliates, unless otherwise noted. | Visit vwr.com to view our privacy policy, trademark owners, and additional disclaimers. © 2019 Avantor, Inc. All rights reserved.

1218 Lit. No. 230027W