


VWR cleanroom stationery & accessories

01. STATIONERY MANUFACTURED FROM HIGHEST QUALITY CLEANROOM COMPATIBLE MATERIALS

02. PROTECT BOTH YOUR PROCESS AND PRODUCT WITH "CLASS 10" CONSUMABLES



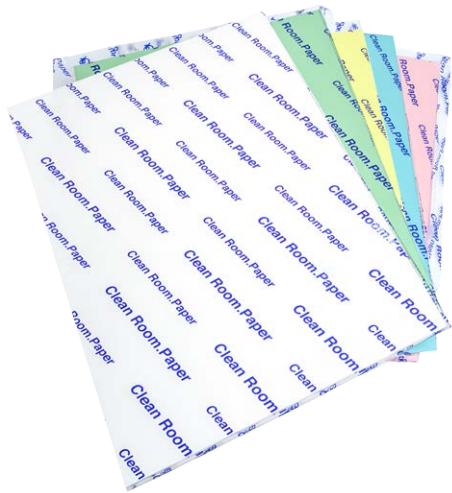

VWR® CLEANROOM PAPER

- Ideal for documentation in critical environments where very low particle and ESD generation is important
- Class 10 certified
- All options are latex-free except for Cat. No. 89422-724


Color	Size	Cat. No.	Case of	Size	Cat. No.	Case of
	22# Weight			28# Weight		
White	8.5 x 11	89422-730	2,500	8.5 x 11	89422-740	2,500
	8.5 x 14	89422-732	1,250	8.5 x 14	89422-742	1,250
	11 x 17	89422-724*	1,250	11 x 17	89422-734	1,250
	11 x 17	89422-728	1,250		-	
Blue	8.5 x 11	10769-742	2,500	8.5 x 11	10769-766	2,500
	8.5 x 14	10769-758	1,250	8.5 x 14	10769-776	1,250
	11 x 17	10769-750	1,250	11 x 17	10769-786	1,250
Canary	8.5 x 11	10769-744	2,500	8.5 x 11	10769-768	2,500
	8.5 x 14	10769-760	1,250	8.5 x 14	10769-778	1,250
	11 x 17	10769-752	1,250	11 x 17	10769-788	1,250
Green	8.5 x 11	10769-746	2,500	8.5 x 11	10769-770	2,500
	8.5 x 14	10769-762	1,250	8.5 x 14	10769-780	1,250
	11 x 17	10769-754	1,250	11 x 17	10769-772	1,250
Cream	8.5 x 11	76207-642	2,500	8.5 x 11	76207-666	2,500
	8.5 x 14	76207-650	1,250	8.5 x 14	76207-674	1,250
	11 x 17	76207-658	1,250	11 x 17	76207-682	1,250
Goldenrod	8.5 x 11	76207-644	2,500	8.5 x 11	76207-668	2,500
	8.5 x 14	76207-652	1,250	8.5 x 14	76207-676	1,250
	11 x 17	76207-660	1,250	11 x 17	76207-684	1,250
Grey	8.5 x 11	76207-646	2,500	8.5 x 11	76207-670	2,500
	8.5 x 14	76207-654	1,250	8.5 x 14	76207-678	1,250
	11 x 17	76207-662	1,250	11 x 17	76207-686	1,250
Ivory	8.5 x 11	76207-648	2,500	8.5 x 11	76207-672	2,500
	8.5 x 14	76207-656	1,250	8.5 x 14	76207-680	1,250
	11 x 17	76207-664	1,250	11 x 17	76207-688	1,250
Pink	8.5 x 11	10769-748	2,500	8.5 x 11	10769-784	2,500
	8.5 x 14	10769-764	1,250	8.5 x 14	10769-782	1,250
	11 x 17	10769-756	1,250	11 x 17	10769-774	1,250


* This paper contains latex
 Three-hole drill can be applied to any case of paper at a minimal cost; contact your VWR sales representative.
 Colors shown are for illustration purposes only.

VWR® SYNTHETIC CLEANROOM PAPER

Synthetic paper is a clay-coated two sided substrate with unique physical properties resistant to water, tearing, grease, and many chemicals. This paper is ideal for documentation in critical environments. 500 sheets/case.

Size	Weight, lbs.	Cat. No.	Case of
8.5 x 11	115	10769-790	500
11 x 17	115	10769-792	500

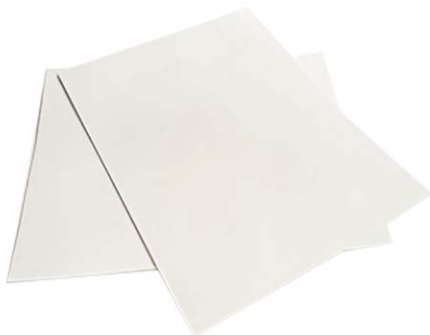

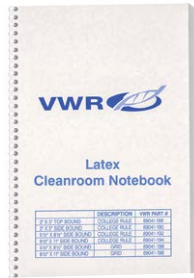

VWR® CLEANROOM SPIRAL NOTEBOOKS

Spiral bound notebooks feature latex paper in college-rule or 6.4 mm (1/4") grid styles.

- Latex paper
- Semi-transparent, high-density polyethylene cover
- Fully recyclable pages

Description	Size, W x L, in.	No. of Pages	Spiral Location	Cat. No.	Case of
College-Rule	3 x 5	100	Top	89041-188	30
College-Rule	3 x 5	100	Side	89041-190	30
College-Rule	5½ x 8½	100	Side	89041-192	30
College-Rule	5½ x 8½	100	Side	10027-956	10
College-Rule	5½ x 8½	200	Side	10027-952	10
College-Rule	8½ x 11	100	Side	89041-194	20
College-Rule	8½ x 11	100	Side	10027-954	10
College-Rule	8½ x 11	200	Side	10027-950	10
Grid-Lined	5½ x 8½	100	Side	89041-196	30
Grid-Lined	8½ x 11	100	Side	89041-198	20

VWR® CLEANROOM SPIRAL NOTEBOOKS, LATEX-FREE

Spiral bound notebooks feature latex-free paper in college-rule or 6.4 mm (1/4") grid styles. Each notebook has 100 pages (50 sheets).

- Latex-free paper
- Semi-transparent, high-density polyethylene cover
- Fully recyclable pages

Description	Size, W x L, in.	Spiral Location	Cat. No.	Case of
College-Rule	3 x 5	Side	12345-038	30
College-Rule	3 x 5	Top	12345-036	30
College-Rule	5½ x 8½	Side	12345-040	30
College-Rule	5½ x 8½	Side	12345-046	30
College-Rule	8½ x 11	Side	12345-042	20
Grid-Lined	5½ x 8½	Side	12345-050	30
Grid-Lined	8½ x 11	Side	12345-052	20



VWR® CRITICAL PRINT™ CLEANROOM CHART RECORDER PAPER

- Manufactured for test, measurement, and production equipment used in a cleanroom environment
- Polyethylene roll core

Description	For Use With	Length, ft.	Width, in.	Cat. No.	Case of
Roll	Alpha Stepper™, Tencor®, Sony®, and Mitsubishi®	60	4.33	51128-004	20
Roll	Nanometrics®	60	2.24	51280-836	20



VWR® AUTOCLAVABLE PAPER

For applications requiring water resistance and the ability to be written on when wet, including use in an autoclave. Also available with the end-user logo printed in a faint screen on one side. Optional two-holes drilled at top of sheet (contact your VWR sales representative).

Description	Size, W x L, in.	Cat. No.	Case of
Autoclavable Paper, Blank	8½ x 11	76314-504	4,000
Autoclavable Paper, with Logo	8½ x 11	76314-502	4,000



VWR® SLEEVE SHEET PROTECTOR

Non-particulating, translucent sleeves are designed to protect documents from harsh environments.

- Three-hole punched
- ESD safe


Description	W x L, in.	Cat. No.	Pack of
Sleeve Protector	8½ x 11	51280-868	100



VWR® CLEANROOM CLIPBOARD

- Nonparticulating nickel-coated clip and spring
- Long lasting and very durable, 1/4" thick
- Use for 8.5" x 11" sheets


Description	Cat. No.	Case of
Cleanroom Clipboard	10027-960	10

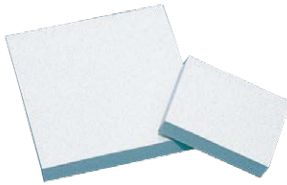

VWR® CRITICAL PRINT™ STICKY NOTES

- Manufactured from 110g/m² (30#) low-particulating stock
- Each pad includes 100 white sticky notes

Size, W x L, in.	Packaging	Cat. No.	Case of
3 x 3	12 Pads/Pack, 2 Packs/Case	51281-824	24
3 x 3	Individually Wrapped	47745-726	24

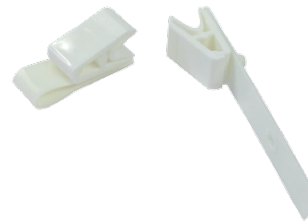

VWR® CRITICAL PRINT™ CLIP-ON NOTEPAD

Each pad has ten sheets and a plastic and a cleanroom-compatible badge clip.

- Designed for use on garments without pockets

Description	W x L, in.	Cat. No.	Pack of
Clip Only	2 x 3	51733-010	50



VWR® CLEANROOM TAB DIVIDERS

Description	Cat. No.	Pack of
Tab Dividers	51280-832	5



800 932 5000 | VWR.COM

Prices, product, and/or services details are current when published and subject to change without notice. | Certain products or services may be limited by federal, state, provincial, or local regulations. | VWR, part of Avantor, makes no claims or warranties concerning sustainable/green products. Any claims concerning sustainable/green products are the sole claims of the manufacturer and not those of VWR International, LLC and/or Avantor, Inc. or affiliates. All prices are in US dollars unless otherwise noted. Offers valid in US and Canada, void where prohibited by law or company policy, while supplies last. | Trademarks are owned by Avantor, Inc. or its affiliates, unless otherwise noted. | Visit vwr.com to view our privacy policy, trademark owners, and additional disclaimers. © 2019 Avantor, Inc. All rights reserved.